




FLEXIBLE METAL SQUEEZE CONNECTORS - DIE CAST ZINC

90° Squeeze Connectors Die Cast Zinc
N/A

B64.1

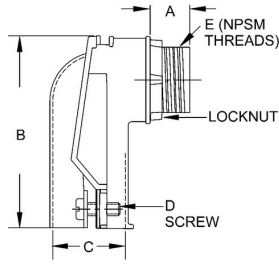

Catalog #: 2694

APPLICATIONS

For use in dry locations to bond flexible metal conduit to a box or enclosure
N/A

PRODUCT FEATURES

Rugged metallic construction insures mechanical protection for the raceway

UL LISTED

Standard 514B, File E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 1 in.

DRAWING DIMENSIONS

Dimension A: 17/32 in.
Dimension B: 2-27/32 in.
Dimension C: 1-7/64 in - 1-53/64 in.
Dimension D: NO. 12 x 1 in.
Dimension E: 1 in. - 11-1/2 NPSM

PACKAGING

Package Type: Carton
Std. Pkg.: 5
Ship Carton Qty.: 50
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 30.00
Ship Carton Length (in.): 19.00
Ship Carton Width (in.): 10.62
Ship Carton Height (in.): 5.31
Ctn Weight (Lbs.): 19.00
UPC Number: 050169026946
I2of5: 50050169026941