




**FLEXIBLE METAL SQUEEZE CONNECTORS - DIE CAST ZINC**

90° Squeeze Connectors Die Cast Zinc  
N/A

B64.1

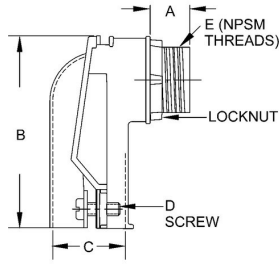

Catalog #: 2695

**APPLICATIONS**

For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A

**PRODUCT FEATURES**

Rugged metallic construction insures mechanical protection for the raceway

**UL LISTED**

Standard 514B, File E195969

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size: 1-1/4 in.

**DRAWING DIMENSIONS**

Dimension A: 19/32 in.  
Dimension B: 3-15/16 in.  
Dimension C: 1-3/8 in - 2-1/16 in.  
Dimension D: NO. 12 x 1 in.  
Dimension E: 1-1/4 in. - 1 1/2 NPSM

**PACKAGING**

Package Type: Carton  
Std. Pkg.: 10  
Ship Carton Qty.: 40  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 50.10  
Ship Carton Length (in.): 19.00  
Ship Carton Width (in.): 10.95  
Ship Carton Height (in.): 8.00  
Ctn Weight (Lbs.): 20.04  
UPC Number: 050169026953  
I2of5: 50050169026958