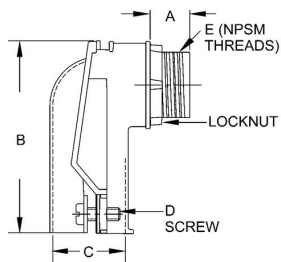


**FLEXIBLE METAL SQUEEZE CONNECTORS - DIE CAST ZINC****90° Squeeze Connectors Die Cast Zinc**
N/A**B64.1**

Catalog #: 2696

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**

Rugged metallic construction insures mechanical protection for the raceway

UL LISTED

Standard 514B, File E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/2 in.

DRAWING DIMENSIONS

Dimension A:	45/64 in.
Dimension B:	6-1/16 in.
Dimension C:	1-27/32 in. - 2-1/16 in.
Dimension D:	NO. 1/4-20 x 1-1/2 in.
Dimension E:	1-1/2 in. - 11-1/2 NPSM

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	5
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	114.40
Ship Carton Length (in.):	8.68
Ship Carton Width (in.):	8.70
Ship Carton Height (in.):	6.20
Ctn Weight (Lbs.):	5.72
UPC Number:	050169026960
I2of5:	50050169026965