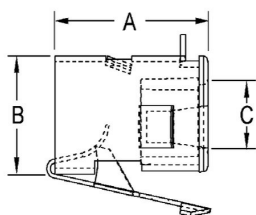


**REDI-LOC[®] SNAP-IN TYPE CONNECTORS****REDI-LOC[®] Cable Connectors Steel**
N/A**B71**

Catalog #: 2700-8

APPLICATIONS

RACO REDI-LOC[®] metal clad cable connectors are designed for use in dry locations for connecting MCI, MCI-A, AC, and HCF cable into a box or enclosure
RACO REDI-LOC[®] II is used to terminate and secure MC, MCI, MCI-A, and AC into a 1/2 in. knockout

PRODUCT FEATURES

No tools needed to assemble to end of cable or to install into box or enclosure
Preassembled anti-short bushing will not fall out during installation
Easy installation - push the cable into the fitting, push connector into the box or enclosure
Can be removed without tools, and is reusable
Rugged one-piece design
Fits all standard 1/2 in. knockouts
Made from steel, and nylon (bushing)
Zinc electro plated for corrosion protection
Tri-lingual (English, Spanish, and French) installation instructions included in each unit carton
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

UL LISTED

File E195966

CULUS

N/A

US PATENTS

US Patents 6,034,326 and 6,020,557

GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.
Cable Size: MCI: AL .434 - .530; MCI: Steel .400 - .530; MCI-A: Steel (.440 - .510); AC: Steel/AL 14-2 (.400) to 12-3

DRAWING DIMENSIONS

Dimension A: 1.070 in.
Dimension B: .840 in.
Dimension C: .375 in.

PACKAGING

Package Type: Carton
Std. Pkg.: 1
Ship Carton Qty.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 3.50
Ship Carton Length (in.): 6.25
Ship Carton Width (in.): 4.50
Ship Carton Height (in.): 2.88
Ctn Weight (Lbs.): 0.88
UPC Number: 050169270080
I2of5: 50050169270085