




4 IN. ROUND CEILING FAN PANS, BOXES AND GORILLA-RING®

4 in. Round Ceiling Box - Drawn with Conduit KO's
1-1/2 in. Depth

A34

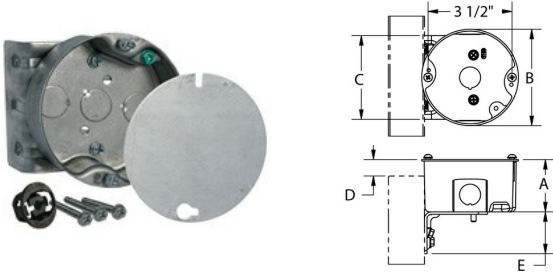

Catalog #: 291-1

APPLICATIONS

RACO® Ceiling Support Boxes are specifically designed for ceiling fan and ceiling or wall light fixture support

PRODUCT FEATURES

- No protruding ground screw or fan mounting screws allows easy installation
- Metal protection plate eliminates debris or damage to wiring
- Easy to follow instructions and mounting hardware included
- #10-32, 1" long ceiling fan screws provided and provision for #8-32 fixture mounting screw
- Graduated markings for 1/2" to 1-1/4" thick sheetrock

US PATENTS

7,148,420; 7,211,744

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.:	70
Fixture (Static) Lbs.:	150

CONFIGURATION

Cable Priouts:	INSIDER®
Bracket Type:	FA, for Wood Joists
Bracket Setback:	1/2 to 1-1/4 in.
Drawn or Welded:	Drawn
Raised Ground:	Yes
Side Knockout(s):	---
Bottom Knockout(s):	(3) 1/2 in.

DRAWING DIMENSIONS

Dimension A:	1-1/2 in.
Dimension B:	4 in.
Dimension C:	3-1/2 in.
Dimension D:	1/2 in.
Dimension E:	1-3/4 in.

PRODUCT MEASUREMENTS

Depth:	1-1/2 in.
Cubic Inches (cm3):	15.8 (258.9)
Wt. Ea. (Lbs.):	1.165
Product Length (in.):	4.06
Product Width (in.):	3.60
Product Height (in.):	4.06

PACKAGING

Minimum Pack Qty.:	10
Std. Pkg.:	10
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	116.50
Ship Carton Length (in.):	11.00
Ship Carton Width (in.):	4.75
Ship Carton Height (in.):	9.25
Ctn Weight (Lbs.):	11.65
Pallet Qty:	1280
UPC Number:	050169029114
I2of5:	50050169029119