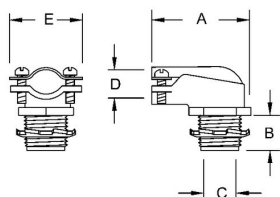


**AC CABLE 90 DEGREE SQUEEZE TYPE****90° Squeeze Connectors, Insulated Throat Malleable Iron**  
N/A**B69**

Catalog #: 3203-8

**APPLICATIONS**

For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A  
For use in dry locations to bond armored cable to a box or enclosure

**PRODUCT FEATURES**

All malleable iron construction insures mechanical protection for the raceway  
Electro zinc plated for added corrosion protection  
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

**CULUS**

UL Listed E195969

**GENERAL PRODUCT INFORMATION**

Sub Class: Insulated  
Trade Size: 3/4 in.

**DRAWING DIMENSIONS**

Dimension A: 2-1/2 in.  
Dimension B: 1/2 in.  
Thread Spec. B: 3/4 in. - 14 NPS  
Dimension C: .822 in.  
Dimension D: .830-1.110 in.  
Dimension E: 1-31/32 in.

**PACKAGING**

Package Type: Carton  
Std. Pkg.: 1  
Ship Carton Qty.: 20  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 27.50  
Ship Carton Length (in.): 10.00  
Ship Carton Width (in.): 5.25  
Ship Carton Height (in.): 4.31  
Ctn Weight (Lbs.): 5.50  
UPC Number: 050169320389  
I2of5: 50050169320384