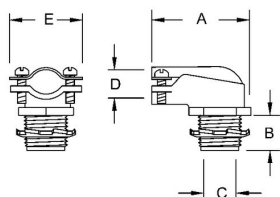


**FLEXIBLE METAL 90 DEGREE SQUEEZE CONNECTORS****90° Squeeze Connectors Malleable Iron**  
N/A**B63**

Catalog #: 3204

**APPLICATIONS**For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A**PRODUCT FEATURES**All malleable iron construction insures mechanical protection for the raceway  
Electro zinc plated for added corrosion protection  
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation**CULUS**

UL Listed E195969

**GENERAL PRODUCT INFORMATION**Sub Class: Insulated  
Trade Size: 1 in.**DRAWING DIMENSIONS**Dimension A: 2-27/32 in.  
Dimension B: 33/64 in.  
Thread Spec. B: 1 in. - 11-1/2 NPS  
Dimension C: .950 in.  
Dimension D: 1.295 in. MAX  
Dimension E: 2-11/32 in.**PACKAGING**Package Type: Carton  
Ship Carton Qty.: 25  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 62.10  
Ship Carton Length (in.): 8.25  
Ship Carton Width (in.): 8.25  
Ship Carton Height (in.): 6.00  
Ctn Weight (Lbs.): 16.15  
UPC Number: 050169032046  
I2of5: 50050169032041