




MC CABLE DOUBLE BITE SADDLE CONNECTORS

90° Double Bite Saddle Connectors Steel/Malleable Iron
N/A

B74

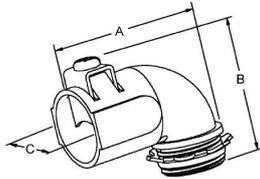

Catalog #: 3204DB

APPLICATIONS

Use 3/8 in. to 1 in. RACO Double Bite Saddle connectors in dry locations to connect flexible metal conduit, MCI, MCI-A, and AC cable to a box or enclosure
Use 1-1/4 in. to 4 in. in dry locations to connect flexible metal conduit to a box or enclosure

PRODUCT FEATURES

- Straight connectors have all steel construction that ensures mechanical protection for raceways
- Straight connectors are available in 3/8 in. to 4 in. trade sizes
- 90 degree connectors have malleable iron and steel construction for added strength
- 90 degree connectors are available in 3/8 in. to 1 in. trade sizes
- Dual saddle clamp ensures proper conduit and cable connection for raceway
- Zinc plated for corrosion protection
- Tri-head screw/clamp design - connectors can be installed by using a slotted, Phillips, or Robertson head screwdriver
- Insulated throats on all Double Bite connectors provide maximum wire protection
- N/A

UL LISTED

Standard 514B, File E195972
Standard 514B, File E195973

NEMA

NEMA FB-7
NEMA FB-8

GENERAL PRODUCT INFORMATION

Trade Size: 1 in.

DRAWING DIMENSIONS

Dimension A: 2-13/16 in.
Dimension B: 2-7/8 in.
Dimension C: 1-11/16 in.

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	5
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	53.10
Ship Carton Length (in.):	5.10
Ship Carton Width (in.):	3.90
Ship Carton Height (in.):	4.10
Ctn Weight (Lbs.):	2.66
UPC Number:	050169532041
I2of5:	50050169532046