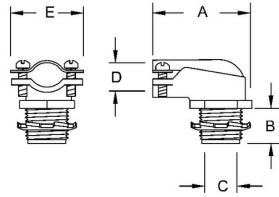


**FLEXIBLE METAL 90 DEGREE SQUEEZE CONNECTORS**90° Squeeze Connectors Malleable Iron
N/A**B63**

Catalog #: 3212

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation**CULUS**

UL Listed E195969

GENERAL PRODUCT INFORMATIONSub Class: Insulated
Trade Size: 3 in.**DRAWING DIMENSIONS**Dimension A: 8-31/32 in.
Dimension B: 1-3/64 in.
Thread Spec. B: 3 in. - 8 NPS
Dimension C: 2.940 in.
Dimension D: 3.025 in. MAX
Dimension E: 5-1/16 in.**PACKAGING**Package Type: Carton
Ship Carton Qty.: 1
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 558.00
Ship Carton Length (in.): 11.20
Ship Carton Width (in.): 5.50
Ship Carton Height (in.): 5.50
Ctn Weight (Lbs.): 5.58
UPC Number: 050169032121
I2of5: 50050169032126