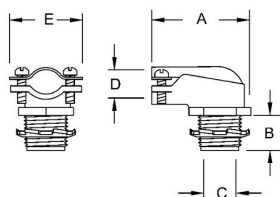


**FLEXIBLE METAL 90 DEGREE SQUEEZE CONNECTORS****90° Squeeze Connectors Malleable Iron**  
N/A**B63**

Catalog #: 3214

**APPLICATIONS**For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A**PRODUCT FEATURES**

All malleable iron construction insures mechanical protection for the raceway  
Electro zinc plated for added corrosion protection  
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

**CULUS**

UL Listed E195969

**GENERAL PRODUCT INFORMATION**

Sub Class: Insulated  
Trade Size: 3-1/2 in.

**DRAWING DIMENSIONS**

Dimension A: 11-15/64 in.  
Dimension B: 1-17/64 in.  
Thread Spec. B: 3-1/2 in. - 8 NPS  
Dimension C: 3.440 in.  
Dimension D: 3.700 in. MAX  
Dimension E: 6-51/64 in.

**PACKAGING**

Package Type: Carton  
Ship Carton Qty.: 1  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 1127.60  
Ship Carton Length (in.): 13.60  
Ship Carton Width (in.): 7.00  
Ship Carton Height (in.): 7.00  
Ctn Weight (Lbs.): 11.28  
UPC Number: 050169032145  
I2of5: 50050169032140