




FLEXIBLE METAL 90 DEGREE SQUEEZE CONNECTORS

90° Squeeze Connectors Malleable Iron
N/A

B63

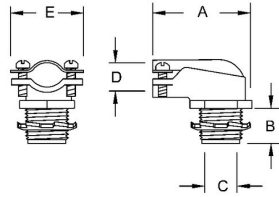

Catalog #: 3216

APPLICATIONS

For use in dry locations to bond flexible metal conduit to a box or enclosure
N/A

PRODUCT FEATURES

All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

CULUS

UL Listed E195969

GENERAL PRODUCT INFORMATION

Sub Class: Insulated
Trade Size: 4 in.

DRAWING DIMENSIONS

Dimension A: 12-11/32 in.
Dimension B: 1-9/16 in.
Thread Spec. B: 4 in. - 8 NPS
Dimension C: 3.935 in.
Dimension D: 4.050 in. MAX
Dimension E: 7-17/64 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 1
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 1450.80
Ship Carton Length (in.): 15.00
Ship Carton Width (in.): 7.60
Ship Carton Height (in.): 7.40
Ctn Weight (Lbs.): 14.51
UPC Number: 050169032169
I2of5: 50050169032164