




FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS

**Straight Squeeze Connectors, Insulated Malleable Iron
N/A**

B61

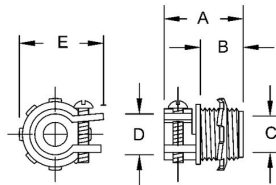

Catalog #: 3302-8

APPLICATIONS

For use in dry locations to bond flexible metal conduit to a box or enclosure
N/A

PRODUCT FEATURES

All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

CULUS

UL Listed E195969

GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.

DRAWING DIMENSIONS

Dimension A: 1-33/64 in.
Dimension B: 17/32 in.
Thread Spec. B: 1/2 in. - 14 NPS
Dimension C: .590 in.
Dimension D: .855 - .910
Dimension E: 1-5/8 in.

PACKAGING

Package Type: Carton
Std. Pkg.: 1
Ship Carton Qty.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 13.90
Ship Carton Length (in.): 8.75
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 4.00
Ctn Weight (Lbs.): 3.48
UPC Number: 050169330289
I2of5: 50050169330284