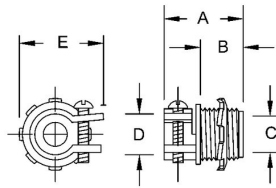


**FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS**Straight Squeeze Connectors, Insulated Malleable Iron
N/A**B61**

Catalog #: 3305

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation**CULUS**

UL Listed E195969

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/4 in.

DRAWING DIMENSIONSDimension A: 1-51/64 in.
Dimension B: 33/64 in.
Thread Spec. B: 1-1/4 in. - 11-1/2 NPT
Dimension C: 1.190 in.
Dimension D: 1.670 MAX
Dimension E: 2-9/16 in.**PACKAGING**Package Type: Carton
Ship Carton Qty.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 47.00
Ship Carton Length (in.): 8.25
Ship Carton Width (in.): 8.25
Ship Carton Height (in.): 6.00
Ctn Weight (Lbs.): 11.75
UPC Number: 050169033050
I2of5: 50050169033055