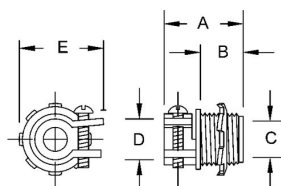


**FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS****Straight Squeeze Connectors, Insulated Malleable Iron**  
N/A**B61**

Catalog #: 3308

**APPLICATIONS**For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A**PRODUCT FEATURES**

All malleable iron construction insures mechanical protection for the raceway  
Electro zinc plated for added corrosion protection  
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

**CULUS**

UL Listed E195969

**GENERAL PRODUCT INFORMATION**

Trade Size: 2 in.

**DRAWING DIMENSIONS**

Dimension A: 2-3/4 in.  
Dimension B: 45/64 in.  
Thread Spec. B: 2 in. - 11-1/2 NPT  
Dimension C: 1.930 in.  
Dimension D: 2.450 MAX  
Dimension E: 3-11/32 in.

**PACKAGING**

Package Type: Carton  
Ship Carton Qty.: 10  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 108.20  
Ship Carton Length (in.): 8.13  
Ship Carton Width (in.): 7.13  
Ship Carton Height (in.): 6.94  
Ctn Weight (Lbs.): 10.82  
UPC Number: 050169033081  
I2of5: 50050169033086