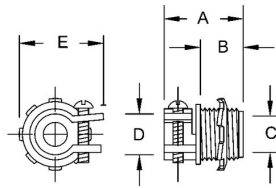


**FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS**Straight Squeeze Connectors, Insulated Malleable Iron
N/A**B61**

Catalog #: 3310

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation**CULUS**

UL Listed E195969

GENERAL PRODUCT INFORMATION

Trade Size: 2-1/2 in.

DRAWING DIMENSIONSDimension A: 3 in.
Dimension B: 1-3/64 in.
Thread Spec. B: 2-1/2 in. - 8 NPS
Dimension C: 2.358 in.
Dimension D: 3.080 MAX
Dimension E: 4-5/32 in.**PACKAGING**Package Type: Carton
Ship Carton Qty.: 1
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 173.60
Ship Carton Length (in.): 5.10
Ship Carton Width (in.): 4.20
Ship Carton Height (in.): 3.40
Ctn Weight (Lbs.): 1.74
UPC Number: 050169033104
I2of5: 50050169033109