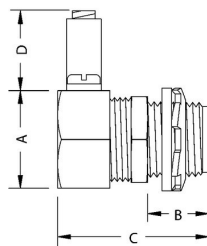


**STRAIGHT GROUNDING CONDUIT AND CORD CONNECTORS****Straight Insulated Connector with Ground Lug, Steel/Malleable Iron  
N/A****B50**

Catalog #: 3520-3

**APPLICATIONS**

For use in outdoor or indoor locations on flexible metallic liquidtight conduit, when installation of a copper or aluminum external bonding jumper is required  
RACO grounding liquidtight connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

**PRODUCT FEATURES**

Patented split gland-ring is designed to slip onto the conduit quickly gripping the jacket of the conduit, speeding installation, assuring a perfect seal, and preventing pullouts  
All components are reusable - RACO liquidtight connectors may be easily disassembled and reused after years of service  
Sealing washer (included) provides a liquidtight seal when terminating the connector in a threadless opening  
Heavy duty locknut included with every RACO liquidtight connector assures continuity of ground  
All metallic components are zinc electro plated for added corrosion protection  
3/8 in. to 1 in. Steel bodies; 1-1/4 in. to 4 in. Malleable Iron bodies  
3/8 in. to 1 in. Steel nuts; 1-1/4 in. to 4 in. Malleable Iron nuts  
N/A

**UL LISTED**

Standard 514B, UL Listed E195969

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size: 2-1/2 in.  
Min. Grounding Wire Capacity: #14 SOL.  
Max Grounding Wire Capacity: #1/0 STR.

**DRAWING DIMENSIONS**

Dimension A: 3-5/8 in.  
Dimension B: 1 in.  
Thread Spec. B: 2-1/2 in. - 8 NPT  
Dimension C: 3-5/16 in.  
Dimension D: 1-11/64 in.

**PACKAGING**

Package Type: Carton  
Ship Carton Qty.: 1  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 335.50  
Ship Carton Length (in.): 5.50  
Ship Carton Width (in.): 4.50  
Ship Carton Height (in.): 4.75  
Ctn Weight (Lbs.): 3.36  
UPC Number: 050169352038  
I2of5: 50050169352033