




**STRAIGHT STRAIN RELIEF CONDUIT AND CORD CONNECTORS**

**Straight Strain Relief Cord Connectors Steel/Malleable Iron**  
N/A

**B57**

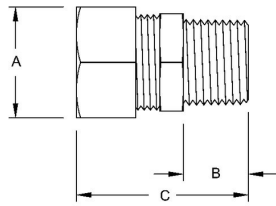

Catalog #: 3704-1

**APPLICATIONS**

For use in wet or dry locations to provide a liquidtight and strain relief termination for flexible cord and cable  
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

**PRODUCT FEATURES**

- All steel/malleable construction provides mechanical strength
- Unique Neoprene grommet design - grommet is forced up and around the cord when the nut is tightened for a positive liquidtight seal
- Washers have cable size range imprinted for identification - eliminates misidentifying inventory
- Use RACO locknuts and sealing washers to complete a liquidtight installation on a sheet metal box or panel
- All metallic components are zinc electro plated for added corrosion protection
- UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation
- 3/8 in. to 1 in. Steel bodies; 1-1/4 in. to 1-1/2 in. Malleable Iron bodies
- 3/8 in. to 1 in. Steel nuts; 1-1/4 in. to 1-1/2 in. Malleable Iron nuts
- N/A

**CULUS**

UL File E195973

**GENERAL PRODUCT INFORMATION**

Trade Size:	1 in.
Cable Range:	.600 - .700
Form Size:	4

**DRAWING DIMENSIONS**

Dimension A:	1-45/64 in.
Dimension B:	19/32 in.
Thread Spec. B:	1 in. - 11-1/2 NPT
Dimension C:	1-51/64 in.

**PACKAGING**

Package Type:	Carton
Ship Carton Qty.:	25
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	32.70
Ship Carton Length (in.):	6.50
Ship Carton Width (in.):	6.50
Ship Carton Height (in.):	5.13
Ctn Weight (Lbs.):	8.18
UPC Number:	050169370414
I2of5:	50050169370419