




STRAIGHT STRAIN RELIEF CONDUIT AND CORD CONNECTORS

Straight Strain Relief Cord Connectors Steel/Malleable Iron
N/A

B57

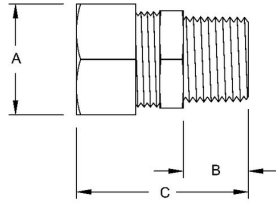

Catalog #: 3704-3

APPLICATIONS

For use in wet or dry locations to provide a liquidtight and strain relief termination for flexible cord and cable
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

- All steel/malleable construction provides mechanical strength
- Unique Neoprene grommet design - grommet is forced up and around the cord when the nut is tightened for a positive liquidtight seal
- Washers have cable size range imprinted for identification - eliminates misidentifying inventory
- Use RACO locknuts and sealing washers to complete a liquidtight installation on a sheet metal box or panel
- All metallic components are zinc electro plated for added corrosion protection
- UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation
- 3/8 in. to 1 in. Steel bodies; 1-1/4 in. to 1-1/2 in. Malleable Iron bodies
- 3/8 in. to 1 in. Steel nuts; 1-1/4 in. to 1-1/2 in. Malleable Iron nuts
- N/A

CULUS

UL File E195973

GENERAL PRODUCT INFORMATION

| | |
|--------------|--------------|
| Trade Size: | 1 in. |
| Cable Range: | .850 - 1.000 |
| Form Size: | 4 |

DRAWING DIMENSIONS

| | |
|-----------------|--------------------|
| Dimension A: | 1-45/64 in. |
| Dimension B: | 19/32 in. |
| Thread Spec. B: | 1 in. - 11-1/2 NPT |
| Dimension C: | 1-51/64 in. |

PACKAGING

| | |
|---------------------------|----------------|
| Package Type: | Carton |
| Ship Carton Qty.: | 25 |
| Product UPC-A Labeled: | No |
| Weight (Lbs. Per/C): | 34.10 |
| Ship Carton Length (in.): | 6.50 |
| Ship Carton Width (in.): | 6.50 |
| Ship Carton Height (in.): | 5.13 |
| Ctn Weight (Lbs.): | 8.53 |
| UPC Number: | 050169370438 |
| I2of5: | 50050169370433 |