




## COLOR-CODED STRAIGHT STRAIN RELIEF CONDUIT AND CORD CONNECTORS

## Color-Coded Straight Strain Relief Cord Connectors Steel

B58.1

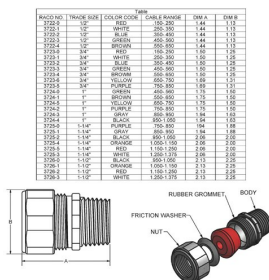

Catalog #: 3723-0

## APPLICATIONS

For use in wet or dry locations to provide a liquidtight and strain relief termination for flexible cord and cable  
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

## PRODUCT FEATURES

Neoprene grommets are color-coded by cable diameter allowing for quick and easy identification  
Steel construction provides mechanical strength and durability  
Metallic components are zinc plated for corrosion protection  
Unique Neoprene grommet design - grommet is forced up and around the cord when the nut is tightened creating a liquidtight seal  
Time saving and easy installation - no need to disassemble the fitting for cord installation  
Male tapered thread NPT  
Use RACO locknuts and sealing washers to complete a liquidtight installation on a sheet metal box or panel  
N/A

## CULUS

UL File E195973

## NEMA

NEMA 4

## COMPLIANCES

MSDS  
[www.hubbell-rtb.com/certifications/Hubbell-RACO\\_MSDS\\_for\\_WP\\_Boxes\\_and\\_Fittings\\_January\\_2015.pdf](http://www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_WP_Boxes_and_Fittings_January_2015.pdf)

## GENERAL PRODUCT INFORMATION

Trade Size: 3/4 in.  
Cable Range: .15 - .25  
Color Code: Red

## DRAWING DIMENSIONS

Dimension A: 1.50  
Dimension B: 1.25

## PACKAGING

Package Type: Carton  
Ship Carton Qty.: 25  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 18.00  
Ship Carton Length (in.): 6.00  
Ship Carton Width (in.): 6.00  
Ship Carton Height (in.): 4.00  
Ctn Weight (Lbs.): 4.50  
UPC Number: 050169983010  
I2of5: 50050169983015