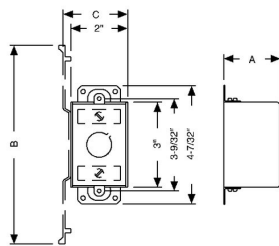


**3 IN. X 2 IN. SWITCH BOXES - 2 TO 3-1/2 IN. DEEP WITH ARMORED CABLE / METAL CLAD / FLEX CLAMPS****2 in. Deep Switch Box - Gangable with Armored Cable/Metal Clad/Flex Clamps
Plaster Ears****A49**

Catalog #: 440

APPLICATIONS

RACO[®] Switch boxes are used to house wiring devices such as switches and outlets
N/A

PRODUCT FEATURES

Gangable switch boxes offer the option of constructing a box to hold two or more devices
Plaster ears allow a box to be used in "old work" applications

UL LISTED

File E195978

COMPLIANCES

All RACO[®] single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Armored Cable/Metal Clad/MCI-A/Flex

CONFIGURATION

End Knockouts: ---
Ends Cable: 4
Bracket Type: No Bracket
Side Knockout(s): ---
Bottom Knockouts(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 2 in.

PRODUCT MEASUREMENTS

Depth: 2 in.
Cubic Inches (cm³): 10.3 (168.8)
Wt. Ea. (Lbs.): 0.535
Product Length (in.): 2.00
Product Width (in.): 4.22
Product Height (in.): 2.00

PACKAGING

Minimum Pack Qty.: 50
Std. Pkg.: 50
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 53.50
Ship Carton Length (in.): 11.38
Ship Carton Width (in.): 8.25
Ship Carton Height (in.): 10.63
Ctn Weight (Lbs.): 26.75
Pallet Qty: 4000
UPC Number: 050169004401
I2of5: 50050169904409