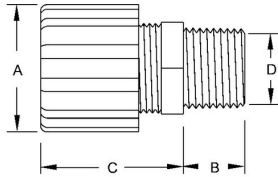


**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - NONMETALLIC**Straight Strain Relief Connectors Nylon
N/A**B59**

Catalog #: 4700-6

APPLICATIONS

For use in dry or wet locations to provide a liquidtight and strain relief termination for flexible cord and cable
 RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

Nylon construction is lightweight and easy to use
 Neoprene grommet
 Resists most common industrial corrosives
 Color-coded Gotcha® ring provides fast identification of cord size
 N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 3/8 in.
 Cable Range: .375 - .437
 Color Code: Blue
 Form Size: 1

DRAWING DIMENSIONS

Dimension A: 63/64 in.
 Dimension B: 7/16 in.
 Dimension C: 1-3/32 in.
 Dimension D: 7/16 in.

PACKAGING

Package Type: Carton
 Ship Carton Qty.: 25
 Product UPC-A Labeled: No
 Weight (Lbs. Per/C): 5.00
 Ship Carton Length (in.): 6.25
 Ship Carton Width (in.): 4.50
 Ship Carton Height (in.): 4.25
 Ctn Weight (Lbs.): 1.25
 UPC Number: 050169470060
 I2of5: 50050169470065