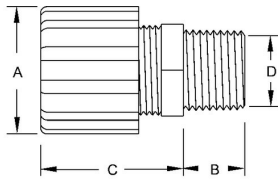


**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - NONMETALLIC****Straight Strain Relief Connectors Nylon**  
N/A**B59**

Catalog #: 4702-5

**APPLICATIONS**

For use in dry or wet locations to provide a liquidtight and strain relief termination for flexible cord and cable  
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

**PRODUCT FEATURES**

Nylon construction is lightweight and easy to use  
Neoprene grommet  
Resists most common industrial corrosives  
Color-coded Gotcha<sup>®</sup> ring provides fast identification of cord size  
N/A

**UL LISTED**

Standard 514B

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size: 1/2 in.  
Cable Range: .375 - .500  
Color Code: Blue  
Form Size: 2

**DRAWING DIMENSIONS**

Dimension A: 1-1/4 in.  
Dimension B: 17/32 in.  
Dimension C: 1-1/2 in.  
Dimension D: 37/64 in.

**PACKAGING**

Package Type: Carton  
Ship Carton Qty.: 25  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 7.40  
Ship Carton Length (in.): 8.75  
Ship Carton Width (in.): 5.00  
Ship Carton Height (in.): 4.00  
Ctn Weight (Lbs.): 1.85  
UPC Number: 050169470251  
I2of5: 50050169470256