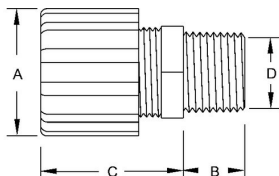


**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - NONMETALLIC****Straight Strain Relief Connectors Nylon**
N/A**B59**

Catalog #: 4703-1

APPLICATIONS

For use in dry or wet locations to provide a liquidtight and strain relief termination for flexible cord and cable
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

Nylon construction is lightweight and easy to use
Neoprene grommet
Resists most common industrial corrosives
Color-coded Gotcha[®] ring provides fast identification of cord size
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 3/4 in.
Cable Range: .375 - .500
Color Code: Blue
Form Size: 3

DRAWING DIMENSIONS

Dimension A: 1-31/64 in.
Dimension B: 35/64 in.
Dimension C: 1-5/8 in.
Dimension D: 49/64 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 15
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 12.10
Ship Carton Length (in.): 8.75
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 4.00
Ctn Weight (Lbs.): 1.82
UPC Number: 050169470312
I2of5: 50050169470317