




STRAIN RELIEF CONDUIT AND CORD CONNECTORS - NONMETALLIC

Straight Strain Relief Connectors Nylon
N/A

B59

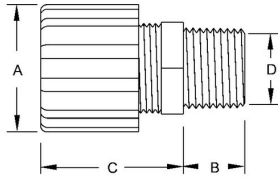

Catalog #: 4704-3

APPLICATIONS

For use in dry or wet locations to provide a liquidtight and strain relief termination for flexible cord and cable
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

- Nylon construction is lightweight and easy to use
- Neoprene grommet
- Resists most common industrial corrosives
- Color-coded Gotcha® ring provides fast identification of cord size
- N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size:	1 in.
Cable Range:	.625 - .750
Color Code:	Yellow
Form Size:	4

DRAWING DIMENSIONS

Dimension A:	1-27/32 in.
Dimension B:	11/16 in.
Dimension C:	1-3/4 in.
Dimension D:	1-1/64 in.

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	10
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	17.50
Ship Carton Length (in.):	8.75
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	1.75
UPC Number:	050169470435
I2of5:	50050169470430