




3 IN. X 2 IN. SWITCH BOXES - 1-1/2 TO 2-1/2 IN. DEEP WITH NONMETALLIC SHEATHED CABLE CLAMPS

2-1/4 in. Deep Switch Boxes - Gangable with Nonmetallic Sheathed Cable Clamps Level Bumps

A50

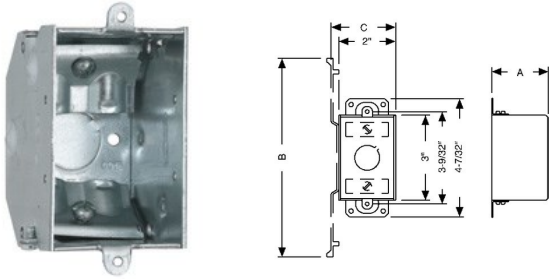

Catalog #: 473

APPLICATIONS

RACO® Switch boxes are used to house wiring devices such as switches and outlets
N/A

PRODUCT FEATURES

Gangable switch boxes offer the option of constructing a box to hold two or more devices
Beveled corner boxes are designed to prevent the clamp screws from protruding into back wall

UL LISTED

File E 195978

COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

CONFIGURATION

End Knockouts: (2) 1/2 in.
Ends Cable: 4
Bracket Type: No Bracket
Side Knockout(s): ---
Bottom Knockout(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 2-1/4 in.

PRODUCT MEASUREMENTS

Depth: 2-1/4 in.
Cubic Inches (cm³): 10.5 (172.1)
Wt. Ea. (Lbs.): 0.505
Product Length (in.): 2.25
Product Width (in.): 3.53
Product Height (in.): 2.00

PACKAGING

Minimum Pack Qty.: 20
Std. Pkg.: 20
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 50.50
Ship Carton Length (in.): 11.00
Ship Carton Width (in.): 5.13
Ship Carton Height (in.): 7.75
Ctn Weight (Lbs.): 10.10
Pallet Qty: 3520
UPC Number: 050169004739
I2of5: 40050169004737