




LIQUIDTIGHT UF CONNECTORS

Underground Feeder, Liquidtight - Nylon
N/A

B79

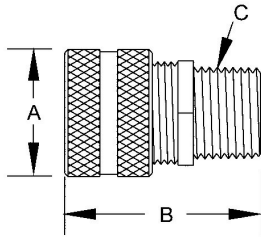

Catalog #: 4799-1

APPLICATIONS

For use with underground feeder (UF) cable to provide a liquidtight connection to meters and enclosures
Use a nylon connector when a lightweight corrosion resistant connection is required

PRODUCT FEATURES

Rugged metallic construction will last the life of the installation
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size:	1/2 in.
Min Grommet Opening:	.20 in. x .40 in.
Max Grommet Opening:	.25 in. x .55 in.
UF Wire Size:	2#14; 2#12; 2#10

DRAWING DIMENSIONS

Dimension A:	1.32 in.
Dimension B:	2.03 in.
Dimension C:	1/2 in. - 14

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	25
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	7.80
Ship Carton Length (in.):	8.75
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	1.95
UPC Number:	050169479919
I2of5:	50050169479914