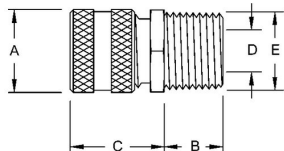


**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - ALUMINUM****Straight Strain Relief Cord Connectors Aluminum**
N/A**B60**

Catalog #: 4802-8

APPLICATIONS

For use in wet or dry locations to provide a liquidtight and strain relief termination for flexible cord and cable
Aluminum liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

Aluminum construction provides a corrosion resistant installation
Patented Gotcha[®] ring incorporates a split hinge design to prevent friction and to provide strain relief
Neoprene grommet
Knurled compression nut allows the fittings to be hand tightened to UL requirements
Gotcha[®] ring is color-coded for sizing identification
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.
Cable Range: .625 - .750
Color Code: Yellow
Form Size: 3

DRAWING DIMENSIONS

Dimension A: 1.38 in.
Dimension B: .55 in.
Dimension C: 1.50 in.
Dimension D: .64 in.
Dimension E: A/C 1.40 in., A/F 1.25 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 15
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 13.90
Ship Carton Length (in.): 8.75
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 4.00
Ctn Weight (Lbs.): 2.09
UPC Number: 050169480281
I2of5: 50050169480286