




**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - ALUMINUM**

**Straight Strain Relief Cord Connectors Aluminum**  
N/A

**B60**

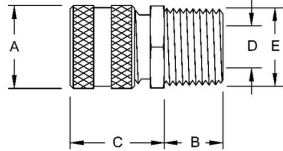

Catalog #: 4803-5

**APPLICATIONS**

For use in wet or dry locations to provide a liquidtight and strain relief termination for flexible cord and cable  
Aluminum liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

**PRODUCT FEATURES**

- Aluminum construction provides a corrosion resistant installation
- Patented Gotcha® ring incorporates a split hinge design to prevent friction and to provide strain relief
- Neoprene grommet
- Knurled compression nut allows the fittings to be hand tightened to UL requirements
- Gotcha® ring is color-coded for sizing identification
- N/A

**UL LISTED**

Standard 514B

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size:	3/4 in.
Cable Range:	.500 - .625
Color Code:	Brown
Form Size:	2

**DRAWING DIMENSIONS**

Dimension A:	1.13 in.
Dimension B:	.55 in.
Dimension C:	1.10 in.
Dimension D:	.64 in.
Dimension E:	A/C 1.29 in., A/F 1.13 in.

**PACKAGING**

Package Type:	Carton
Ship Carton Qty.:	25
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	10.90
Ship Carton Length (in.):	8.75
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	2.73
UPC Number:	050169480359
I2of5:	50050169480354