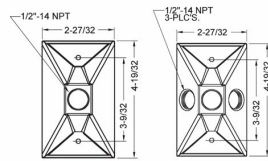


**ROUND & RECTANGULAR CLUSTER COVERS****One Gang Cluster Cover - Three Threaded Outlets****D22**

Catalog #: 5189-7

APPLICATIONS

For use with BELL® single gang or round weatherproof boxes
Cluster covers provide an easy means of mounting BELL® lampholders and other accessories.

PRODUCT FEATURES

Rugged die cast construction
State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
Includes gasket and mounting hardware
Multi-lingual instructions in each package
Three hole covers supplied with two closure plugs

UL LISTED

Standard 514A

CULUS

N/A

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Bronze

CONFIGURATIONNumber Of Outlets: 3
Gangs: 1**PRODUCT MEASUREMENTS**Outlet Size: 1/2 in.
Wt. Ea. (Lbs.): 0.290**PACKAGING**Package Type: Carded
Std. Pkg.: 6
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 29.00
Ship Carton Length (in.): 12.13
Ship Carton Width (in.): 11.75
Ship Carton Height (in.): 3.00
Ctn Weight (Lbs.): 1.74
Pallet Qty: 1080.00
UPC Number: 050169518977
I2of5: 50050169518972