




ROUND & RECTANGULAR CLUSTER COVERS

4 in. Round Cluster Cover - Three Threaded Outlets

D22

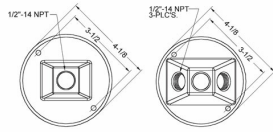

Catalog #: 5197-2

APPLICATIONS

For use with BELL® single gang or round weatherproof boxes
Cluster covers provide an easy means of mounting BELL® lampholders and other accessories.

PRODUCT FEATURES

- Rugged die cast construction
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Includes gasket and mounting hardware
- Multi-lingual instructions in each package
- Three hole covers supplied with two closure plugs

UL LISTED

Standard 514A

CULUS

N/A

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Bronze

CONFIGURATION

Number Of Outlets: 3

PRODUCT MEASUREMENTS

Outlet Size: 1/2 in.
Wt. Ea. (Lbs.): 0.406

PACKAGING

Package Type: Shrink
 Std. Pkg.: 20
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 40.60
 Ship Carton Length (in.): 15.75
 Ship Carton Width (in.): 3.88
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 8.12
 Pallet Qty: 3000.00
 UPC Number: 050169519721
 I2of5: 50050169519726