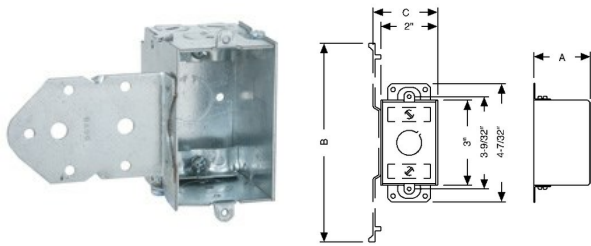


**3 IN. X 2 IN. SWITCH BOXES - 1-1/2 TO 2-1/2 IN. DEEP WITH NONMETALLIC SHEATHED CABLE CLAMPS****2-1/2 in. Deep Switch Boxes - Gangable with Nonmetallic Sheathed Cable Clamps
LB Bracket, 5/8 in. Setback****A50**

Catalog #: 529

APPLICATIONS

RACO® Switch boxes are used to house wiring devices such as switches and outlets
N/A

PRODUCT FEATURES

Gangable switch boxes offer the option of constructing a box to hold two or more devices
Reference the Box Selection section in the front of this catalog for complete description of bracket types and features

UL LISTED

File E195978

COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

CONFIGURATION

End Knockouts: (2) 1/2 in.
Ends Cable: 4
Bracket Type: LB, for Wood Studs
Bracket Setback: 5/8 in.
Side Knockout(s): ---
Bottom Knockouts(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 2-1/2 in.
Dimension B: 1-31/32 in.
Dimension C: 5-3/64 in.

PRODUCT MEASUREMENTS

Depth: 2-1/2 in.
Cubic Inches (cm³): 12.5 (204.8)
Wt. Ea. (Lbs.): 0.685
Product Length (in.): 2.50
Product Width (in.): 4.22
Product Height (in.): 5.59

PACKAGING

Minimum Pack Qty.: 20
Std. Pkg.: 20
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 68.50
Ship Carton Length (in.): 13.25
Ship Carton Width (in.): 7.25
Ship Carton Height (in.): 7.50
Ctn Weight (Lbs.): 13.70
Pallet Qty: 2160
UPC Number: 050169005293
I2of5: 40050169005291