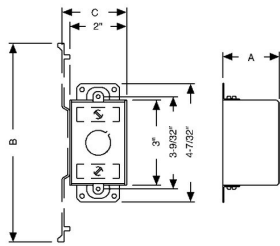


**3 IN. X 2 IN. SWITCH BOXES - 1-1/2 TO 2-1/2 IN. DEEP WITH NONMETALLIC SHEATHED CABLE CLAMPS****2-1/2 in. Deep Switch Boxes - Gangable with Nonmetallic Sheathed Cable Clamps
TS Bracket, 1/2 in. Setback****A50**

Catalog #: 531

APPLICATIONSRACO® Switch boxes are used to house wiring devices such as switches and outlets
N/A**PRODUCT FEATURES**Gangable switch boxes offer the option of constructing a box to hold two or more devices
Reference the Box Selection section in the front of this catalog for complete description of bracket types and features**UL LISTED**

File E195978

COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

CONFIGURATIONEnd Knockouts: (2) 1/2 in.
Ends Cable: 4
Bracket Type: TS, for Metal or Wood Studs
Bracket Setback: 1/2 in.
Side Knockout(s): ---
Bottom Knockouts(s): (1) 1/2 in.**DRAWING DIMENSIONS**Dimension A: 2-1/2 in.
Dimension B: 7 in.
Dimension C: 2-13/64 in.**PRODUCT MEASUREMENTS**Depth: 2-1/2 in.
Cubic Inches (cm³): 12.5 (204.8)
Wt. Ea. (Lbs.): 0.704
Product Length (in.): 2.50
Product Width (in.): 7.00
Product Height (in.): 2.20**PACKAGING**Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 70.40
Ship Carton Length (in.): 11.38
Ship Carton Width (in.): 8.25
Ship Carton Height (in.): 10.63
Ctn Weight (Lbs.): 17.60
Pallet Qty: 2000
UPC Number: 050169005316
I2of5: 40050169005314