




SINGLE GANG BOXES - 2 IN. TO 2-5/8 IN. DEEP

2 in. Deep, with Lugs - Three Threaded Outlets - 4-1/2 in. x 2-3/4 in.
N/A

D04

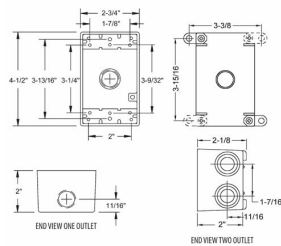

Catalog #: 5324-5

APPLICATIONS

For use in branch circuit wiring in wet, damp, or dry locations
May be used as a weatherproof junction box, or as a housing for receptacles, switches, and GFCI's

PRODUCT FEATURES

Reinforced connector outlets
State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
Eight box mounting options with detachable lugs
Two closure plugs included
Hubs accept all threaded fittings and threaded conduit
Ground screw installed
Multi-lingual instructions in each package
Includes gasket and mounting hardware
N/A

UL LISTED

File E195978

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 3
Gangs: 1

PRODUCT MEASUREMENTS

Depth: 2 in.
Outlet Size: 3/4 in.
Cubic Inches (cm³): 18.3 (299.9)
Wt. Ea. (Lbs.): 0.650

PACKAGING

Package Type: Carded
Std. Pkg.: 6
Product UPC-A Labeled: Yes
Ship Carton Length (in.): 12.13
Ship Carton Width (in.): 11.75
Ship Carton Height (in.): 3.00
Ctn Weight (Lbs.): 3.90
Pallet Qty: 1080.00
UPC Number: 050169532454
I2of5: 50050169532459