




## LAMPHOLDER / COVER COMBOS

4in. Round Cover Combinations for 75-150 Watt Par 38 Lamps  
(1) Lampholder / (1) Cover

D25

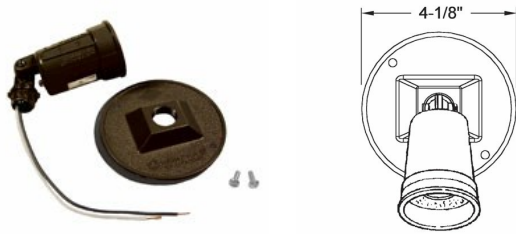

Catalog #: 5624-2

## APPLICATIONS

For general outdoor lighting in wet, damp or dry locations  
For use with BELL® single gang or round weatherproof boxes

## PRODUCT FEATURES

Rugged die cast construction  
State-of-the-art powder coat finish provides maximum weatherability and scratch resistance  
Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming  
Includes gasket and mounting hardware  
Multi-lingual instructions in each package  
No Need to purchase separate components  
N/A

## UL LISTED

File E225082

## CSA

C22.2 No. 18

## GENERAL PRODUCT INFORMATION

Color: Bronze

## PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.800

## PACKAGING

Package Type:	Shrink
Std. Pkg.:	8
Product UPC-A Labeled:	Yes
Weight (Lbs. Per/C):	80.00
Ship Carton Length (in.):	13.13
Ship Carton Width (in.):	6.50
Ship Carton Height (in.):	8.50
Ctn Weight (Lbs.):	6.40
Pallet Qty:	840.00
UPC Number:	050169562420
I2of5:	50050169562425