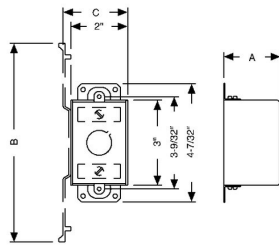


**3 IN. X 2 IN. SWITCH BOXES - 2-3/4 TO 3-1/2 IN. DEEP WITH CONDUIT KO'S****2-3/4 in. Deep Switch Boxes - Gangable with Conduit KO's
Plaster Ears****A48**

Catalog #: 565

APPLICATIONSRACO® Switch boxes are used to house wiring devices such as switches and outlets
N/A**PRODUCT FEATURES**Gangable switch boxes offer the option of constructing a box to hold two or more devices
Plaster ears allow a box to be used in "old work" applications**UL LISTED**

File E 195978

COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Conduit

CONFIGURATIONEnd Knockouts: (2) 3/4 in.
Ends Cable: ---
Bracket Type: No Bracket
Side Knockout(s): (4) 3/4 in.
Bottom Knockouts(s): (2) 1/2 in.**DRAWING DIMENSIONS**

Dimension A: 2-3/4 in.

PRODUCT MEASUREMENTSDepth: 2-3/4 in.
Cubic Inches (cm3): 14.0 (229.4)
Wt. Ea. (Lbs.): 0.597
Product Length (in.): 2.75
Product Width (in.): 4.22
Product Height (in.): 2.00**PACKAGING**Minimum Pack Qty.: 50
Std. Pkg.: 50
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 59.70
Ship Carton Length (in.): 14.50
Ship Carton Width (in.): 8.25
Ship Carton Height (in.): 10.88
Ctn Weight (Lbs.): 29.85
Pallet Qty: 2750
UPC Number: 050169005651
I2of5: 50050169005656