




MASONRY BOXES & SUPPORTS

Masonry Boxes, 2-1/2 in. Deep - Gangable with Conduit KO's
1-Gang, 1-15/16 in. Wide

A59

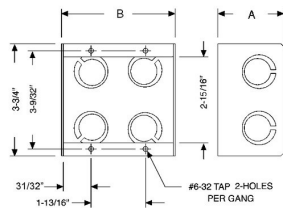

Catalog #: 688

APPLICATIONS

RACO® Masonry boxes are designed to accommodate the mounting of switches or other devices in masonry walls
 2-1/2" deep boxes are used in 4" block walls, 3-1/2" deep boxes are used in 6" or 8" block walls
 Gangable masonry boxes offer the option of constructing a box to hold two or more devices

PRODUCT FEATURES

- Rugged welded design does not fall apart during construction
- Gangable design allows installer to build unlimited number of gangs to hold multiple devices
- Rectangular shape fits square cuts in block
- Standard 1/2" and 3/4" TKO® knockouts
- Device ears inside the box prevent mortar from getting in the device holes
- Steel voltage partition #675 fits 2-1/2" and #676 fits 3-1/2" depth
- Forward mounted grounding provision allows for easy installation of grounding pigtail
- Standard wall plates can be used
- N/A

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Conduit

CONFIGURATION

End Knockouts: (2) TKO®
 Gangs: 1
 Side Knockout(s): 4 TKO®
 Bottom Knockouts(s): (2) TKO®

DRAWING DIMENSIONS

Dimension A: 2-1/2 in.
 Dimension B: 1-15/16 in.

PRODUCT MEASUREMENTS

Depth: 2-1/2 in.
 Cubic Inches (cm3): 15.5 (254.0)
 Wt. Ea. (Lbs.): 0.682
 Product Length (in.): 2.50
 Product Width (in.): 3.75
 Product Height (in.): 1.94

PACKAGING

Minimum Pack Qty.: 20
 Std. Pkg.: 20
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 68.20
 Ship Carton Length (in.): 11.00
 Ship Carton Width (in.): 5.25
 Ship Carton Height (in.): 8.25
 Ctn Weight (Lbs.): 13.64
 Pallet Qty: 2000
 UPC Number: 050169006887
 I2of5: 50050169006882