




MASONRY BOXES & PARTITIONS

Masonry Boxes, 2-1/2 in. Deep - Nongangable with Conduit KO's
3-Gang, 5-19/32 in. Wide

A58

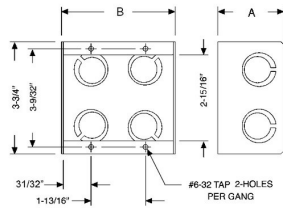

Catalog #: 692

APPLICATIONS

RACO® Masonry boxes are designed to accommodate the mounting of switches or other devices in masonry walls
2-1/2" deep boxes are used in 4" block walls, 3-1/2" deep boxes are used in 6" or 8" block walls

PRODUCT FEATURES

- Rugged welded design does not fall apart during construction
- Available from one to six gang configurations in both 2-1/2" and 3-1/2" depths
- Rectangular shape fits square cuts in block
- Large volume design allows for additional work room inside the box
- Standard 1/2" and 3/4" concentric knockouts
- Device ears inside the box prevent mortar from getting in the device holes
- Steel voltage partition #971 fits all 2-1/2" or 3-1/2" depths
- Standard wall plates can be used
- N/A

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Conduit

CONFIGURATION

End Knockouts: 6 Conc.
 Drawn or Welded: Welded
 Gangs: 3
 Side Knockout(s): 6 Conc.
 Bottom Knockout(s): 3 Conc.

DRAWING DIMENSIONS

Dimension A: 2-1/2 in.
 Dimension B: 5-19/32 in.

PRODUCT MEASUREMENTS

Depth: 2-1/2 in.
 Cubic Inches (cm³): 47.8 (783.3)
 Wt. Ea. (Lbs.): 1.250
 Product Length (in.): 2.50
 Product Width (in.): 3.75
 Product Height (in.): 5.59

PACKAGING

Minimum Pack Qty.: 10
 Std. Pkg.: 10
 Product UPC-A Labeled: No
 Weight (Lbs. Per/C): 125.00
 Ship Carton Length (in.): 11.25
 Ship Carton Width (in.): 8.50
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 12.50
 Pallet Qty: 1000
 UPC Number: 050169006924
 I2of5: 50050169006929