




## ROUND CEILING NON-METALLIC CABLE BOXES

**SADDLE BOX® 4 in. Round Ceiling Fan and Fixture Box - For Nonmetallic Sheathed Cable or Conduit**  
**SADDLE BOX®, 12.5 Cu. in.**

A81.1

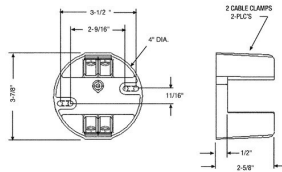

Catalog #: 7120-1

### APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires  
Provide excellent protection for wiring system or devices

### PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install  
Self-clamping wire entry clamps  
Round fixture boxes offer an optional front-mounted grounding screw  
For use wherever fans (Cat. #7120, 7120-1, 7120VB only) or lighting canopies are to be installed

### UL LISTED

File E 195963

### COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book  
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book  
Federal Manufacturer's number 28488

### FIRE RESISTANCE

2-hour fire rating, UL Orange Book

### US PATENTS

5234119

### OTHER PATENTS

Mexico 179,825

### GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable  
Color: Black

### RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: 70  
Fixture (Static) Lbs.: 210

### CONFIGURATION

Cable Clamps: 4  
Side Knockout(s): ---  
Bottom Knockouts(s): ---

### DRAWING DIMENSIONS

Dimension A: 2-5/8 in.

### PRODUCT MEASUREMENTS

Depth: 2-5/8 in.  
Cubic Inches (cm<sup>3</sup>): 12.5 (204.8)  
Wt. Ea. (Lbs.): 0.258  
Product Length (in.): 2.60  
Product Width (in.): 3.90  
Product Height (in.): 4.00

### PACKAGING

Minimum Pack Qty.: 24  
Std. Pkg.: 24  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 25.80

Ship Carton Length (in.):	15.50
Ship Carton Width (in.):	6.25
Ship Carton Height (in.):	8.25
Ctn Weight (Lbs.):	6.19
Pallet Qty:	2520
UPC Number:	050169712016
I2of5:	50050169712011