




ROUND CEILING NON-METALLIC CABLE BOXES

SADDLE BOX® 4 in. Round Ceiling Fan and Fixture Box - For Nonmetallic Sheathed Cable or Conduit
SADDLE BOX®, 12.5 Cu. in.

A81.1

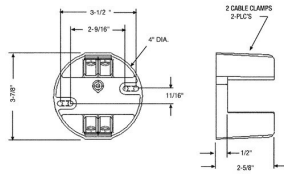

Catalog #: 7120

APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Provide excellent protection for wiring system or devices

PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Self-clamping wire entry clamps
Round fixture boxes offer an optional front-mounted grounding screw
For use wherever fans (Cat. #7120, 7120-1, 7120VB only) or lighting canopies are to be installed

UL LISTED

File E 195963

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

US PATENTS

5234119

OTHER PATENTS

Mexico 179,825

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Black

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: 70
Fixture (Static) Lbs.: 210

CONFIGURATION

Cable Clamps: 4
Side Knockout(s): ---
Bottom Knockouts(s): ---

DRAWING DIMENSIONS

Dimension A: 2-5/8 in.

PRODUCT MEASUREMENTS

Depth: 2-5/8 in.
Cubic Inches (cm3): 12.5 (204.8)
Wt. Ea. (Lbs.): 0.368
Product Length (in.): 2.60
Product Width (in.): 3.90
Product Height (in.): 4.00

PACKAGING

Minimum Pack Qty.: 20
Std. Pkg.: 20
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 36.80

Ship Carton Length (in.):	14.50
Ship Carton Width (in.):	9.13
Ship Carton Height (in.):	8.75
Ctn Weight (Lbs.):	7.35
Pallet Qty:	1600
UPC Number:	050169071205
I2of5:	50050169071200