




ROUND CEILING NON-METALLIC CABLE BOXES

3-1/2 in. Round Ceiling Set-up - For Spanning from Joist to Joist - For Nonmetallic Sheathed Cable
2-5/8 in. Deep, 18.0 Cu. in., 1/2 in. Setback, Adj. 14-3/4 in - 22-1/2 in.

A81

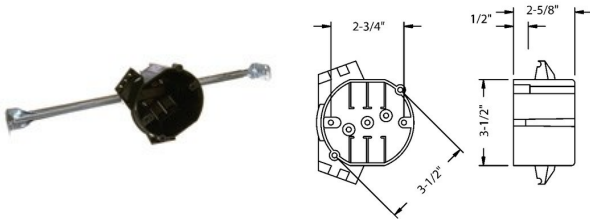

Catalog #: 7307

APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Provide excellent protection for wiring system or devices
RACO® 7907, 7307, 7825, and 7826RAC are not designed for ceiling fan support

PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Self-clamping wire entry clamps
Round fixture boxes offer an optional front-mounted grounding screw

UL LISTED

File R16536

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

US PATENTS

4,874,905; 4,605,816; 4,580,689; 4,666,055

OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Black

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No
Fixture (Static) Lbs.: 10*

CONFIGURATION

Cable Clamps: 4

DRAWING DIMENSIONS

Dimension A: 2-5/8 in.

PRODUCT MEASUREMENTS

Depth: 2-5/8 in.
Cubic Inches (cm3): 18.0 (295.0)
Wt. Ea. (Lbs.): 0.604
Product Length (in.): 3.50
Product Width (in.): 4.25
Product Height (in.): 15.25

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 60.40
Ship Carton Length (in.): 20.00
Ship Carton Width (in.): 7.50

Ship Carton Height (in.):	13.50
Ctn Weight (Lbs.):	15.10
Pallet Qty:	1050
UPC Number:	050169073070
I2of5:	50050169073075