




SINGLE GANG NON-METALLIC CABLE BOXES - WITH CAPTIVE NAILS

Single-gang with Captive Nails - For Nonmetallic Sheathed Cable
3-3/16 in. Deep, 20.3 Cu. in., Nails, 1/2 in. Setback

A75

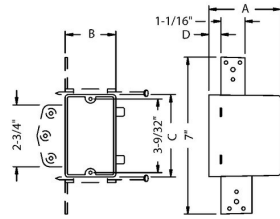

Catalog #: 7820RAC

APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Accommodates wiring devices such as switches and receptacles
Provide excellent protection for wiring system or devices

PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Single-gang boxes have knockouts that break out quickly and cleanly for faster installation
Positioning tabs for fast accurate mounting on studs or joists
Oversized nail support that resists hammer impact and prevents box deformation

UL LISTED

File E 195963

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Gray

CONFIGURATION

Cable Knockouts(s): 4

DRAWING DIMENSIONS

Dimension A: 3-3/16 in.
Dimension C: 3-19/32 in.
Dimension D: 1/2 in.

PRODUCT MEASUREMENTS

Depth: 3-3/16 in.
Cubic Inches (cm³): 20.3 (332.6)
Wt. Ea. (Lbs.): 0.244
Product Length (in.): 3.19
Product Width (in.): 3.84
Product Height (in.): 2.25

PACKAGING

Minimum Pack Qty.: 100
Std. Pkg.: 100
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 24.40
Ship Carton Length (in.): 24.00
Ship Carton Width (in.): 13.00
Ship Carton Height (in.): 16.00
Ctn Weight (Lbs.): 24.40
Pallet Qty: 1600
UPC Number: 050169978207
I2of5: 50050169978202