




## ROUND NON-METALLIC CABLE BOXES

4 in. Round Ceiling Boxes - With Captive Nails for Nonmetallic Sheathed Cable  
2-3/8 in. Deep, 20.0 Cu. in., 3/8 in. Setback, Nails

A80

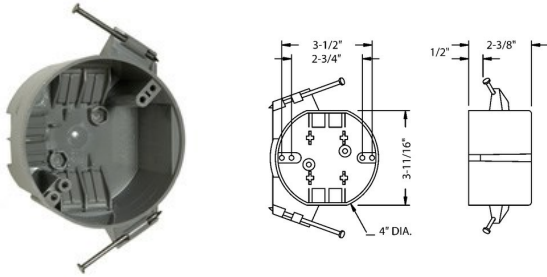

Catalog #: 7824RAC

### APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires  
Provide excellent protection for wiring system or devices  
For use wherever lighting fixture canopies are to be installed - not designed for ceiling fan support

### PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install  
Self-clamping wire entry clamps  
Round fixture boxes offer an optional front-mounted grounding screw  
Oversized nail support that resists hammer impact and prevents box deformation

### UL LISTED

File E 195963

### COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book  
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book  
Federal Manufacturer's number 28488

### FIRE RESISTANCE

2-hour fire rating, UL Orange Book

### US PATENTS

4,874,905; 4,605,816; 4,580,689; 4,666,055

### OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

### GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable  
Color: Gray

### RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No  
Fixture (Static) Lbs.: 50

### CONFIGURATION

Cable Clamps: 4

### DRAWING DIMENSIONS

Dimension A: 2-3/8 in.

### PRODUCT MEASUREMENTS

Depth: 2-3/8 in.  
Cubic Inches (cm3): 20.0 (327.7)  
Wt. Ea. (Lbs.): 0.214  
Product Length (in.): 2.38  
Product Width (in.): 6.00  
Product Height (in.): 4.25

### PACKAGING

Minimum Pack Qty.: 75  
Std. Pkg.: 75  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 21.40  
Ship Carton Length (in.): 24.00

Ship Carton Width (in.):	13.00
Ship Carton Height (in.):	16.00
Ctn Weight (Lbs.):	16.05
Pallet Qty:	1125
UPC Number:	050169978245
I2of5:	50050169978240