




## ROUND CEILING NON-METALLIC CABLE BOXES

4 in. Round Ceiling Set-up - For Spanning from Joist to Joist - For Nonmetallic Sheathed Cable  
2-3/8 in. Deep, 20.0 Cu. in., Adj. 14-3/4 in - 22-1/2 in.

A81

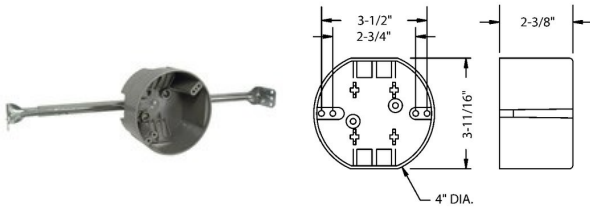

Catalog #: 7826RAC

### APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires  
Provide excellent protection for wiring system or devices  
RACO® 7907, 7307, 7825, and 7826RAC are not designed for ceiling fan support

### PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install  
Self-clamping wire entry clamps  
Round fixture boxes offer an optional front-mounted grounding screw

### UL LISTED

File E195963

### COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book  
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book  
Federal Manufacturer's number 28488

### FIRE RESISTANCE

2-hour fire rating, UL Orange Book

### US PATENTS

4,874,905; 4,605,816; 4,580,689; 4,666,055

### OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

### GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable  
Color: Black

### RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No  
Fixture (Static) Lbs.: 10\*

### CONFIGURATION

Cable Clamps: 6

### DRAWING DIMENSIONS

Dimension A: 2-3/8 in.

### PRODUCT MEASUREMENTS

Depth: 2-3/8 in.  
Cubic Inches (cm3): 18.0 (295.0)  
Wt. Ea. (Lbs.): 0.617  
Product Length (in.): 2.38  
Product Width (in.): 3.69  
Product Height (in.): 14.75

### PACKAGING

Minimum Pack Qty.: 25  
Std. Pkg.: 25  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 61.70  
Ship Carton Length (in.): 19.90  
Ship Carton Width (in.): 7.50

Ship Carton Height (in.):	13.70
Ctn Weight (Lbs.):	15.43
Pallet Qty:	1050
UPC Number:	050169078266
I2of5:	50050169078261