




MULTI GANG NON-METALLIC CABLE BOXES - WITH CAPTIVE NAILS

Multi-gang, Large Capacity, with Captive Nails - for Wood Stud or Face Mounted to Wood or Metal Stud -- For Nonmetallic Sheathed Cable
3-7/8 in. Deep, Two-gang, Nails, 1/2 in. Setback, Bracket

A76

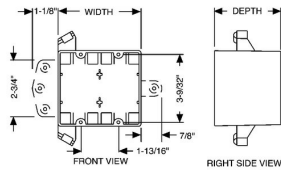

Catalog #: 7848RAC

APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Accommodates wiring devices such as switches and receptacles
Provide excellent protection for wiring system or devices

PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Self-clamping wire entry clamps
Positioning tabs for fast accurate mounting on studs or joists
Oversized nail support that resists hammer impact and prevents box deformation

UL LISTED

File E 195963

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating (except 7645RAC), (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

US PATENTS

4,605,816; 4,580,689; 4,666,055

OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Gray

CONFIGURATION

Cable Knockouts(s): ---
Cable Clamps: 8

DRAWING DIMENSIONS

Dimension A: 3-7/8 in.

PRODUCT MEASUREMENTS

Depth: 3-7/8 in.
Cubic Inches (cm3): 48.0 (786.5)
Wt. Ea. (Lbs.): 0.421
Product Length (in.): 3.96
Product Width (in.): 6.45
Product Height (in.): 4.00

PACKAGING

Minimum Pack Qty.: 50
Std. Pkg.: 50
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 42.10
Ship Carton Length (in.): 24.00
Ship Carton Width (in.): 16.00
Ship Carton Height (in.): 20.25
Ctn Weight (Lbs.): 18.05

Pallet Qty:
UPC Number:
I2of5:

600
050169978481
50050169978486