




## MULTI GANG NON-METALLIC CABLE BOXES - WITH CAPTIVE NAILS

Multi-gang, Large Capacity, with Captive Nails - for Wood Stud or Face Mounted to Wood or Metal Stud -- For Nonmetallic Sheathed Cable  
3-7/8 in. Deep, Three-gang, Nails, 1/2 in. Setback, Bracket

A76

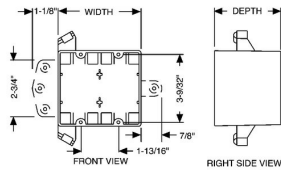

Catalog #: 7874RAC

### APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires  
Accommodates wiring devices such as switches and receptacles  
Provide excellent protection for wiring system or devices

### PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install  
Self-clamping wire entry clamps  
Positioning tabs for fast accurate mounting on studs or joists  
Oversized nail support that resists hammer impact and prevents box deformation

### UL LISTED

File E 195963

### COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book  
Boxes are listed for mechanical properties, including the 2-hour Fire Rating (except 7645RAC), (building codes) UL Orange Book  
Federal Manufacturer's number 28488

### US PATENTS

4,605,816; 4,580,689; 4,666,055

### OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

### GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable  
Color: Gray

### CONFIGURATION

Cable Knockouts(s): ---  
Cable Clamps: 12

### DRAWING DIMENSIONS

Dimension A: 3-7/8 in.

### PRODUCT MEASUREMENTS

Depth: 3-7/8 in.  
Cubic Inches (cm3): 74.0 (1212.6)  
Wt. Ea. (Lbs.): 0.564  
Product Length (in.): 3.95  
Product Width (in.): 6.06  
Product Height (in.): 8.44

### PACKAGING

Minimum Pack Qty.: 50  
Std. Pkg.: 50  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 56.40  
Ship Carton Length (in.): 24.00  
Ship Carton Width (in.): 24.00  
Ship Carton Height (in.): 20.25  
Ctn Weight (Lbs.): 29.25  
Pallet Qty: 600  
UPC Number: 050169978740  
I2of5: 50050169978745