


**3 IN. X 2 IN. SWITCH BOXES - 2-3/4 TO 3-1/2 IN. DEEP WITH CONDUIT KO'S****3-1/2 in. Deep Switch Boxes - Gangable with Conduit KO's  
Plaster Ears**

A48

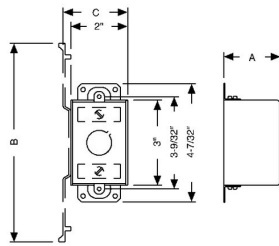

Catalog #: 8590

**APPLICATIONS**

RACO® Switch boxes are used to house wiring devices such as switches and outlets  
N/A

**PRODUCT FEATURES**

Gangable switch boxes offer the option of constructing a box to hold two or more devices  
Plaster ears allow a box to be used in "old work" applications

**UL LISTED**

File E 195978

**COMPLIANCES**

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

**FIRE RESISTANCE**

Acceptable for use in 2-hour rated walls

**GENERAL PRODUCT INFORMATION**

Wiring System: Conduit

**CONFIGURATION**

End Knockouts: (2) 1/2 in.  
Ends Cable: ---  
Bracket Type: No Bracket  
Side Knockout(s): (4) 1/2 in.  
Bottom Knockouts(s): (1) 1/2 in.

**DRAWING DIMENSIONS**

Dimension A: 3-1/2 in.

**PRODUCT MEASUREMENTS**

Depth: 3-1/2 in.  
Cubic Inches (cm<sup>3</sup>): 18.0 (295.0)  
Wt. Ea. (Lbs.): 0.736  
Product Length (in.): 3.50  
Product Width (in.): 4.22  
Product Height (in.): 2.00

**PACKAGING**

Minimum Pack Qty.: 25  
Std. Pkg.: 25  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 73.60  
Ship Carton Length (in.): 18.25  
Ship Carton Width (in.): 8.00  
Ship Carton Height (in.): 7.00  
Ctn Weight (Lbs.): 18.40  
Pallet Qty: 2100  
UPC Number: 050169005903  
I2of5: 50050169005908