




## WELDED GANG BOXES WITH CONDUIT KO'S

Gang Boxes, 1-5/8 in. Deep - Welded with Conduit KO's  
9-Gang

A54

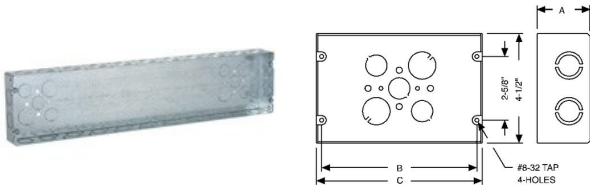

Catalog #: 958

### APPLICATIONS

RACO® Gang boxes are used where a number of wiring devices are to be centrally located

### PRODUCT FEATURES

- Gang boxes save time in installation, no need to gang boxes together
- Have 1/2" and 3/4" concentric KO's for use with a wide variety of wiring methods
- Bottom KO pattern, 3-1/2" and 2-3/4" at either end of box
- Accepts two styles of covers, flat and 3/4" raised device cover
- Use low voltage partitions #947 or #949

### UL LISTED

File E195978

### GENERAL PRODUCT INFORMATION

Wiring System: Conduit

### CONFIGURATION

Top & Bottom Knockouts(s): (22) 1/2-3/4 in. Concentric  
 Back Knockout(s): (6) 1/2 in. & (4) 3/4 in.  
 Gangs: 9  
 Side Knockout(s): (4) 1/2-3/4 in. Concentric

### DRAWING DIMENSIONS

Dimension A: 1-5/8 in.  
 Dimension B: 19-1/16 in.  
 Dimension C: 19-1/2 in.

### PRODUCT MEASUREMENTS

Depth: 1-5/8 in.  
 Cubic Inches (cm3): 137.3 (2249.9)  
 Wt. Ea. (Lbs.): 3.250  
 Product Length (in.): 1.63  
 Product Width (in.): 4.50  
 Product Height (in.): 19.50

### PACKAGING

Minimum Pack Qty.: 1  
 Std. Pkg.: 1  
 Product UPC-A Labeled: No  
 Weight (Lbs. Per/C): 325.00  
 Ship Carton Length (in.): 20.00  
 Ship Carton Width (in.): 2.44  
 Ship Carton Height (in.): 4.88  
 Ctn Weight (Lbs.): 3.25  
 Pallet Qty: 144  
 UPC Number: 050169009581  
 I2of5: 50050169009586