




MASONRY BOXES & PARTITIONS

Masonry Boxes, 2-1/2 in. Deep - Nongangable with Conduit KO's
6-Gang, 11-1/32 in. Wide

A58

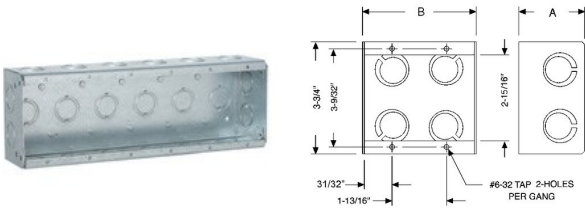

Catalog #: 960

APPLICATIONS

RACO® Masonry boxes are designed to accommodate the mounting of switches or other devices in masonry walls
2-1/2" deep boxes are used in 4" block walls, 3-1/2" deep boxes are used in 6" or 8" block walls

PRODUCT FEATURES

- Rugged welded design does not fall apart during construction
- Available from one to six gang configurations in both 2-1/2" and 3-1/2" depths
- Rectangular shape fits square cuts in block
- Large volume design allows for additional work room inside the box
- Standard 1/2" and 3/4" concentric knockouts
- Device ears inside the box prevent mortar from getting in the device holes
- Steel voltage partition #971 fits all 2-1/2" or 3-1/2" depths
- Standard wall plates can be used
- N/A

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Conduit

CONFIGURATION

End Knockouts: 12 Conc.
 Drawn or Welded: Welded
 Gangs: 6
 Side Knockout(s): 9 Conc.
 Bottom Knockouts(s): 6 Conc.

DRAWING DIMENSIONS

Dimension A: 2-1/2 in.
 Dimension B: 11-1/32 in.

PRODUCT MEASUREMENTS

Depth: 2-1/2 in.
 Cubic Inches (cm³): 95.3 (1561.6)
 Wt. Ea. (Lbs.): 2.400
 Product Length (in.): 2.56
 Product Width (in.): 3.75
 Product Height (in.): 11.03

PACKAGING

Minimum Pack Qty.: 1
 Std. Pkg.: 1
 Product UPC-A Labeled: No
 Weight (Lbs. Per/C): 240.00
 Ship Carton Length (in.): 11.63
 Ship Carton Width (in.): 4.25
 Ship Carton Height (in.): 4.25
 Ctn Weight (Lbs.): 2.40
 Pallet Qty: 320
 UPC Number: 050169009604
 I2of5: 50050169009609