


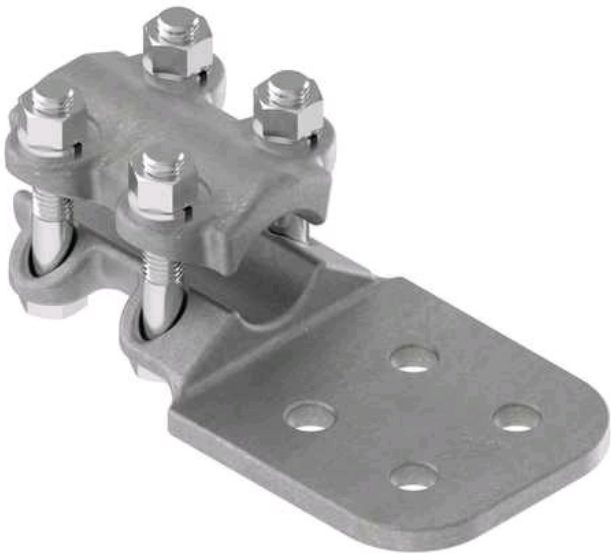

* Representative image

Terminal, Aluminum Compression

by ANDERSON
Catalog ID: ACF1000B

Terminal, Aluminum Compression, Cable to 2-hole Flat, cable range 1.092-1.196. OBSOLETE, DELETE FROM PIM

Product Details

General

Material	Aluminum
Number of Bolt Holes	2
Number of Ground Braid Lug Holes	0
Number of Pad Holes	2
Type	Terminal, Cable to Flat
UPC	096359278962

Dimensions

Angle - Pad	180 °
Base Hole Spacing	0 in
Diameter - Base Holes	0 in
Diameter - Bolt	0 in
Diameter - Inside	0 in
Length - Coupling	0 in
Length Before Compression	0 in
Weight	1.666 lb
Width - Pad	1.5 in

Electrical Ratings

Maximum Current Rating Amps Continuous	0
--	---

Conductor Related

Conductor Compatibility	ACSR-Cuckoo-795-24/7;ACSR-Drake-795-26/7;ACSR-Condor-795-54/7;ACSR-Mallard-795-30/19;ACSR-Ruddy-900-45/7;ACSR-Canary-900-54/7;ACSR-Rail-954-45/7;ACSR-Cardinal-954-54/7;AAC-Cockscomb-900-37;AAC-Snapdragon-900-61;AAC-Magnolia-954-37;AAC-Goldenrod-954-61;AAC-Camellia-1000-61;AAC-Bluebell-1033.5-37;AAC-Larkspur-1033.5-61
-------------------------	--

Conductor Diameter - Maximum	1.196 in
Conductor Diameter - Minimum	1.092 in
Conductor Diameter Range	1.092 - 1.196
Conductor Type	• AAC • ACSR

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscs@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com