


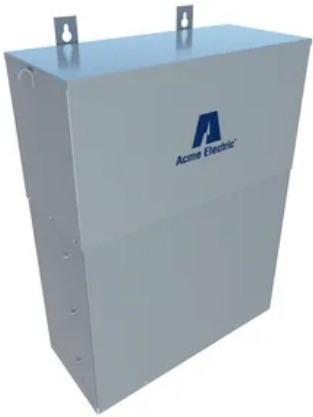

Panel-Tran Zone Power Centers - Three Phase, 480? - 208Y/120V, 15kVA, Bolt In Breakers, 304 Stainless Steel

By Acme Electric
Catalog # [PTBB3150015SS](#)



Panel-Tran Zone Power Centers - Three Phase, 480? - 208Y/120V, 15kVA, Bolt In Breakers, 304 Stainless Steel

Features

- Fully compliant with NEC 450-3
- Designed for indoor and outdoor applications
- Electrostatic shield for enhanced protection
- Primary and Secondary main circuit breakers provided

General

ANFC Taps	-
BNFC Taps	2
Catalog Number	PTBB3150015SS
Construction	Encapsulated
Electrostatic Shield	Shielded
Max Temperature Rise	115 Degrees Celsius
Mounting Type	Wall
Primary Breaker	ED43B040L (40A)
Primary Voltage	480
Product Category	Panel-Tran Zone Power Centers
Secondary Breaker	B350H (50A)
Secondary Voltage	208Y/120 V
Taps % Steps	5%
UL Insulation Class	180°C
UPC	047503090299
Winding Material	CU
kVA	15

Dimensions

Dimensions	12.38 in x 22.13 in x 35.13 in
------------	--------------------------------

Height	35.13 in
Length	12.38 in
Weight	385 lb
Width	22.13 in

Electrical Ratings

Frequency Rating	60 Hz
Primary Voltage	480D V

Certifications And Compliance

CSA Standard	C22.2 No 47
Nema Rating	NEMA 3R
UL Standard	UL 1062

Logistics

Carton Quantity	1
Pallet Quantity	1

Product Assets

- [Customer Notices - Prop 65 - Cancer & Reproductive Harm Notice](#)
- [SDS - HCC SDS](#)
- [Specifications - PTBB3150015SS Specification Sheet English](#)
- [Specifications - PTBB3150015SS](#)
- [Specifications - PTBB3150015SS](#)
- [Terms and Conditions - HCC Terms & Conditions](#)